


Accessories for Fieldbus Systems


 
T-splitter

RSV-2RKV 49

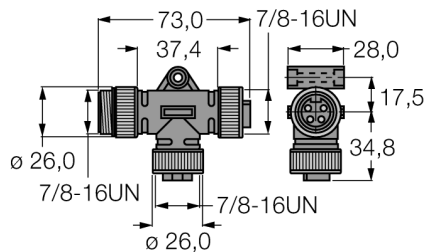


- 4-pole T-splitter with 7/8" stainless steel receptacle connections
- For use in FOUNDATION™ fieldbus applications

FOUNDATION™ fieldbus Connection

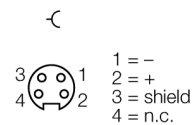

Wiring Diagram

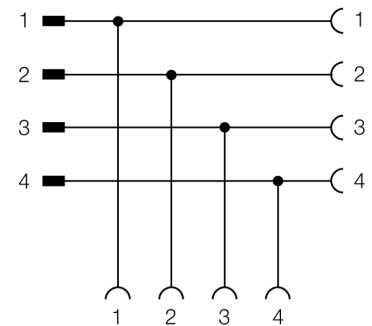

Type designation	RSV-2RKV 49
Ident-No.	U2385-7
Splitter	Tee, 7/8"
Number of contacts	4
Connector body	Plastic, PUR, Yellow
Connector B	Female, 2x, 7/8", Straight
Connector body	Plastic, PUR, Yellow
Contact carriers	Plastic, PUR, Black
Contacts	Metal, CuZn, Gold-plated
Coupling nut	Stainless Steel, 1.4404
Seal	Plastic
Protection class	When coupled - IP67, Only in screwed condition
Mechanical life	> 100 Mating cycles
Pollution degree	3/2
Connector	Connector, 1x, 7/8", straight
Grip	plastic, PUR, yellow
Contact carriers	plastic, PUR, Black
Contacts	Metal, CuZn, Gold-plated
Coupling nut/screw	stainless steel, 1.4404
Protection class	When coupled - IP67, only when plugged in
Mechanical lifespan	> 100 Mating cycles
Pollution degree	3/2
Rated voltage	250 V
Current	4 A
forward resistance	≤ 5 mΩ
Insulation resistance	≥ 10 ⁹ Ω
Ambient temperature junction	-40...+80°C