 


技术数据


外壳材料	镀铬铝
电气连接	接插件, M12 × 1
	8针，径向
轴轴向负载能力	20 N
轴径向负载能力	40 N
环境条件	
工作温度	-20...+85 °C
抗震动性(EN 60068-2-6)	100 m/s ² , 55...2000 Hz
抗冲击性(EN 60068-2-27)	1000 m/s ² , 6 ms
防护等级	IP65
防护等级 (轴型 / 轴套)	IP50

附件


RCS-15-06-04	1545363
波纹管联轴器外径：15 mm，孔径： 6 mm/4 mm	



RCS-15-06-06	1545362
波纹管联轴器外径：15 mm，孔径： 6 mm/6 mm	

 


RCS-15-08-06	1545361
波纹管联轴器外径：15 mm，孔径： 8 mm/6 mm	

 


RA-BC-20-06-06	100048777
带铝制轮毂的波纹管联轴器Ø 20 mm； d1 = 6 mm，d2 = 6 mm	



RA-BC-20-06-08	100048778
带铝制轮毂的波纹管联轴器Ø 20 mm； d1 = 6 mm，d2 = 8 mm	

 

RA-BC-20-06-10	100048779
带铝制轮毂的波纹管联轴器Ø 20 mm； d1 = 6 mm，d2 = 10 mm	

 

RA-BC-E-20-06-06	100048785
不锈钢波纹管联轴器Ø 20 mm；d1 = 6 mm， d2 = 6 mm	




RA-BC-E-20-06-10	100048786
不锈钢波纹管联轴器Ø 20 mm；d1 = 6 mm， d2 = 10 mm	



100048790



 100048795







附件

尺寸图	型号	货号	
	RKC8T-2/TXL	6625142	连接线缆，M12母头接插件，直式8针， 线缆长度2 m，护套材质PUR，黑色； cULus认证
	WKC8T-2/TXL	6625145	连接线缆，M12母头接插件，弯式8针， 线缆长度2 m，护套材质PUR，黑色； cULus认证

附件

尺寸图	型号	货号	
mm [inch]	RA-SAB-5-20	100038292	小型增量编码器弹簧臂（带36.5 mm和40 mm法兰）；建议接触压力5 N，最大接触压力20 N
mm [inch]	RA-MW-200-5.5-DK1-6	100038295	用于编码器的铝制测量轮（网状滚花）；周长0.2 m，宽度5.5 mm，深度=6 mm
mm [inch]	RA-MW-200-6.5-PS1-6	100038296	用于编码器的铝制测量轮（光面PU材质）；周长0.2 m，宽度6.5 mm，深度=6 mm

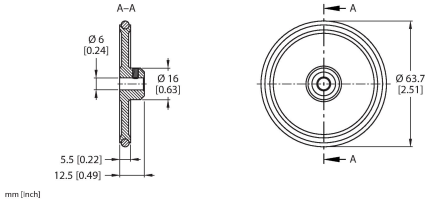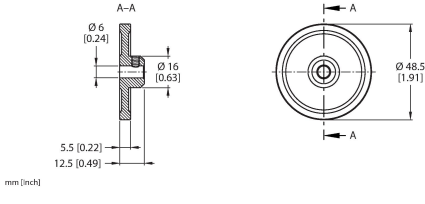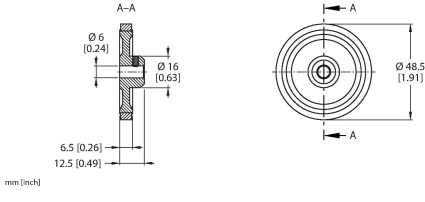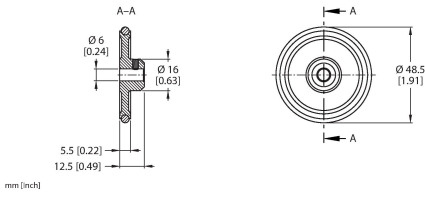尺寸图	型号	货号	
	RA-MW-200-5.5-OR1-6	100038298	用于编码器的铝制测量轮（O型圈）；周长0.2 m，宽度5.5 mm，深度 = 6 mm
	RA-MW-B0-5.5-DK1-6	100038299	用于编码器的铝制测量轮（网状滚花）；周长6"，宽度5.5 mm，深度 = 6 mm
	RA-MW-B0-6.5-PS1-6	100038300	用于编码器的铝制测量轮（光面PU材质）；周长6"，宽度6.5 mm，深度 = 6 mm
	RA-MW-B0-5.5-OR1-6	100038301	用于编码器的铝制测量轮（O型圈）；周长6"，宽度5.5 mm，深度 = 6 mm