 
 
 
 
 
 
 
 


Technical data

Housing material	Die-cast zinc
Electrical connection	Connector, M12 × 1
	8-pin
Axial shaft load	50 N
Radial shaft load	100 N
Environmental conditions	
Ambient temperature	-40...+85 °C
Vibration resistance (EN 60068-2-6)	300 m/s ² , 10...2000 Hz
Shock resistance (EN 60068-2-27)	3000 m/s ² , 6 ms
Protection class	IP67
Protection class shaft	IP67

Accessories

RA-BC-20-06-10 	100048779 Bellows coupling with aluminum hub Ø 20 mm; d1 = 6 mm, d2 = 10 mm
RA-BC-20-10-10 	100048782 Bellows coupling with aluminum hub Ø 20 mm; d1 = 10 mm, d2 = 10 mm
RA-BC-E-20-06-10 	100048786 Stainless steel bellows coupling Ø 20 mm; d1 = 6 mm, d2 = 10 mm
RA-BC-E-20-10-12 	100048788 Stainless steel bellows coupling Ø 20 mm; d1 = 10 mm, d2 = 12 mm
RA-SDC-30-10-12 	100048793 Spring disc coupling Ø 30 mm; d1 = 10 mm, d2 = 12 mm
RA-BC-20-08-10 	100048781 Bellows coupling with aluminum hub Ø 20 mm; d1 = 8 mm, d2 = 10 mm
RA-BC-20-10-12 	100048783 Bellows coupling with aluminum hub Ø 20 mm; d1 = 10 mm, d2 = 12 mm
RA-BC-E-20-10-10 	100048787 Stainless steel bellows coupling Ø 20 mm; d1 = 10 mm, d2 = 10 mm
RA-SDC-30-10-10 	100048792 Spring disc coupling Ø 30 mm; d1 = 10 mm, d2 = 10 mm
RA-HC-25-10-10 	100048796 Aluminum helix coupling Ø 25 mm; d1 = 10 mm, d2 = 10 mm

RA-HC-25-10-12

100048797

Aluminum helix coupling Ø 25 mm; d1 = 10 mm, d2 = 12 mm



RFA-2

1544631

Aluminium flange adapter, rectangular, for solid shaft encoders with clamping flange; edge length 63.5 mm; 3 mm thick



RFA-13

1544642

Aluminium flange adapter, rectangular, for solid shaft encoders with clamping flange; edge length 80 mm; 4 mm thick



RFA-1

1544630

Aluminium flange adapter, rectangular, for solid shaft encoders with clamping flange; edge length 58 mm; 4 mm thick



RFA-4

1544633

Euro flange – aluminium flange adapter for solid shaft encoders, Ø 115 mm; reference diameter 100 mm; adapts 58 mm clamping flange to Euro flange



RFA-6

1544635

Aluminium flange adapter for solid shaft encoders with clamping flange, Ø 58 mm; adapts clamping flange to synchro flange



RFA-7

1544636

Aluminium flange adapter for solid shaft encoders, Ø 65 mm; adapts to Ø 65 mm flange and 48 mm reference diameter



RFA-8

1544637

Aluminium flange adapter for solid shaft encoders with clamping flange, Ø 70 mm; thickness 4 mm, adapts to Ø 70 mm flange



RFA-9

1544638


Aluminium angle flange for solid shaft encoders with Ø 58 mm clamping flange



RFA-11

1544640

Aluminium flange adapter for solid shaft encoders with clamping flange, Ø 70 mm; thickness 10 mm, adapts to Ø 70 mm flange

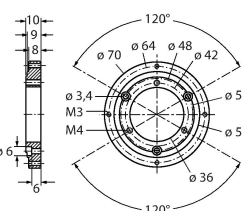

RFA-121544641

Aluminium flange adapter, rectangular, for solid shaft encoders with clamping flange; edge length 70 mm; 10 mm thick







Accessories

Dimension drawing	Type	ID	
	RKC8T-2/TXL	6625142	Connection cable, M12 female connector, straight, 8-pin, cable length: 2 m, jacket material: PUR, black; cULus approval
	WKC8T-2/TXL	6625145	Connection cable, M12 female connector, angled, 8-pin, cable length: 2 m, jacket material: PUR, black; cULus approval

Accessories

Dimension drawing	Type	ID	
	RA-MW-200-12-DK1-10	100038302	Aluminum measuring wheel (cross knurled) for encoders; circumference 0.2 m, width 12 mm, D = 10 mm
	RA-MW-200-12-PS1-10	100038303	Aluminum measuring wheel (smooth PU) for encoders; circumference 0.2 m, width 12 mm, D = 10 mm
	RA-MW-200-12-RT1-10	100038304	Aluminum measuring wheel (studded PU) for encoders; circumference 0.2 m, width 12 mm, D = 10 mm

Dimension drawing	Type	ID	
	RA-MW-200-12-PC1-10	100038305	Aluminum measuring wheel (grooved PU) for encoders; circumference 0.2 m, width 12 mm, D = 10 mm
	RA-MW-500-25-DK1-10	100038314	Aluminum measuring wheel (cross knurled) for encoders; circumference 0.5 m, width 25 mm, D = 10 mm
	RA-MW-500-25-PS1-10	100038315	Aluminum measuring wheel (smooth PU) for encoders; circumference 0.5 m, width 25 mm, D = 10 mm
	RA-MW-500-25-RT1-10	100038316	Aluminum measuring wheel (studded PU) for encoders; circumference 0.5 m, width 25 mm, D = 10 mm
	RA-MW-500-25-PC1-10	100038317	Aluminum measuring wheel (grooved PU) for encoders; circumference 0.5 m, width 25 mm, D = 10 mm
	RA-MW-300-12-DK1-10	100038306	Aluminum measuring wheel (cross knurled) for encoders; circumference 0.3 m, width 12 mm, D = 10 mm
	RA-MW-300-12-PS1-10	100038307	Aluminum measuring wheel (smooth PU) for encoders; circumference 0.3 m, width 12 mm, D = 10 mm

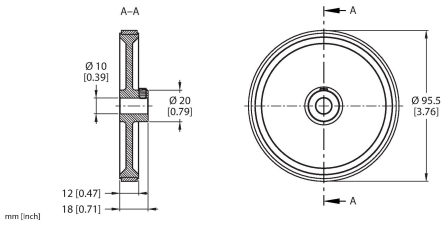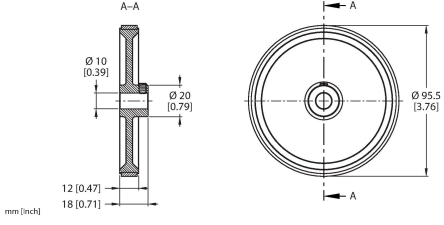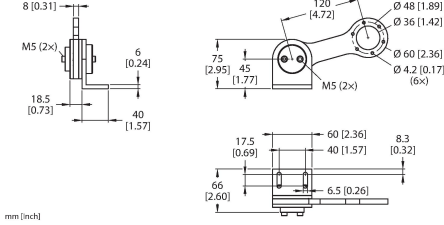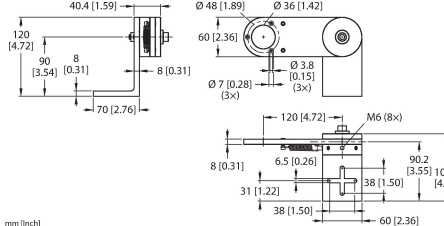Dimension drawing	Type	ID	
	RA-MW-300-12-RT1-10	100038308	Aluminum measuring wheel (studded PU) for encoders; circumference 0.3 m, width 12 mm, D = 10 mm
	RA-MW-300-12-PC1-10	100038309	Aluminum measuring wheel (grooved PU) for encoders; circumference 0.3 m, width 12 mm, D = 10 mm
	RA-SAB-15-36	100038251	Spring arm for encoders with a 58-mm flange; recommended contact pressure 15 N; maximum contact pressure 30 N
	RA-SAB-30-36	100038294	Spring arm for encoders with a 58-mm flange; recommended contact pressure 30 N; maximum contact pressure 40 N