

 
 
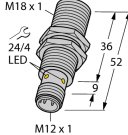
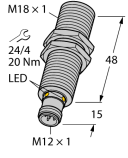
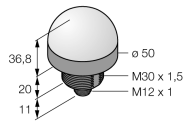
IO-Link Starterkit

Type designation	IO-Link Starterkit
Ident no.	100012813
Included in delivery	Carrying case, black/yellow □ Bottom lining, black, 248 x 182 x 33 mm, account assigned □ Cover profile foam, black, 248 x 182 x 21 mm 1:2 □ Plug-in power supply, 24 VDC 0.5 A Type 512692 — NA with M8 female connector □ 8-GB USB stick with software set □ IO-Link master TBENS2-4IOL (6814024) □ Ethernet cable PSGS4M-RJ45S-4414-1M (6933004) □ Connection cable RKC4T-2-RSC4T/TXL (6625604) □ I/O hub TBILS4-8DXP (100002596) □ Inductive sensor BI10U-M18-IOL6X2-H1141 (1644875) □ Ultrasonic sensor RU40U-M18M-AP8X2-H1151 (1610094) □ Indicator light K50L2RGBKQ (3802158)

- Complete set including IO-Link master, IO-Link sensors, I/O hub, parameterization software and accessories

IO-Link Starterkit

Function accessories

Type code	Ident no.		Dimension drawing
TBEN-S2-4IOL	6814024	Compact multiprotocol I/O module, 4 IO-Link Master 1.1 Class A, 4 universal PNP digital channels 0.5 A	
TBIL-S4-8DIP	100002596	8-channel I/O hub for the connection of 8 digital PNP signals to an IO-Link master (input/output freely selectable per channel)	
BI10U-M18-IOL6X2-H1141	1644875	Inductive sensor, cylindrical; threaded barrel; 18 mm; chrome-plated brass	
RU40U-M18M-AP8X2-H1151	1610094	Ultrasonic sensor; cylindrical, threaded barrel; 18 mm; nickel-plated brass	
K50L2RGBKQ	3802158	RGB LED indicators	

IO-Link Starterkit

Function accessories

Type code	Ident no.		Dimension drawing
RU40U-M18M-AP8X2-H1151/P0001	100032174	Ultrasonic sensor; cylindrical, threaded barrel; 18 mm; nickel-plated brass	