


# RKP46PSA-0.3-RSP46PSA/TXL

## Supply Cable - M12 Power – Extension Cable

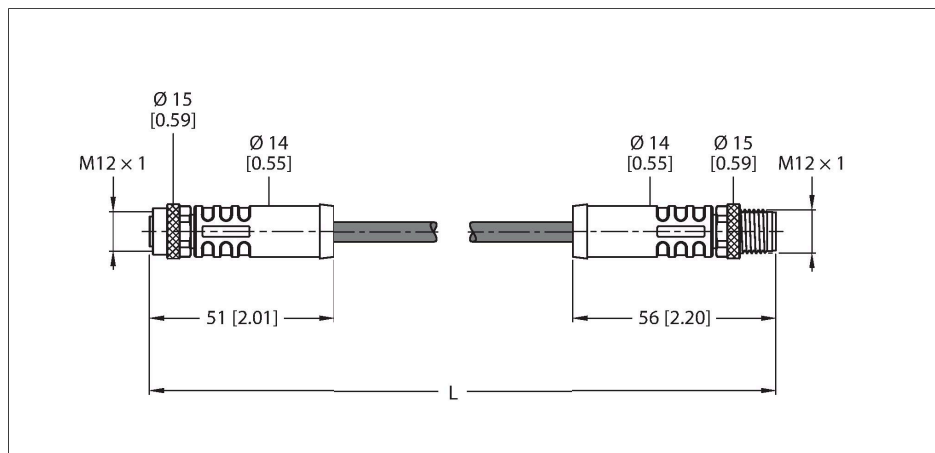

### Technical data

|                              |                                              |
|------------------------------|----------------------------------------------|
| Type                         | RKP46PSA-0.3-RSP46PSA/TXL                    |
| ID                           | 100038841                                    |
| Connector A                  | Female, M12 × 1, Straight, S-coded           |
| Number of pins               | 3+PE                                         |
| Contacts                     | Brass, CuZn, Gold-plated                     |
| Contact carriers             | Plastic, PA, Black                           |
| Connector body               | Plastic, TPU, Black                          |
| Coupling nut/screw           | Brass, CuZn, Nickel-plated                   |
| Seal                         | Plastic, FPM/FKM                             |
| Tightening torque            | 1 Nm                                         |
| Mechanical lifespan          | > 100 Mating cycles                          |
| Pollution degree             | 3                                            |
| Protection class             | IP65, IP67, IP68, Only in screwed condition  |
| Connector B                  | Male, M12 × 1, Straight, S-coded             |
| Number of Pins               | 3+PE                                         |
| Contacts                     | Metal, CuZn, Gold-plated                     |
| Contact carriers             | Plastic, PA, Black                           |
| Connector body               | Plastic, TPU, Black                          |
| Coupling nut/retaining screw | Brass, CuZn, Nickel-plated                   |
| Tightening torque            | 1 Nm                                         |
| Mechanical life              | > 100 Mating cycles                          |
| Pollution degree             | 3                                            |
| Protection class             | IP65, IP67, IP68, Only when screwed together |
| Cable                        |                                              |
| Cable diameter               | Ø 9.6 mm ±0.20                               |
| Cable length                 | 0.3 m                                        |




### Features



- M12 female connector, S-coded, straight, 4-pin (3+PE)
- M12 male connector, S-coded, straight, 4-pin (3+PE)
- Jacket material: PUR
- Jacket color: black
- Highly resistant to oils, coolants, lubricants and emulsions
- Suitable for drag chain use
- Resistant to vibrations and shocks
- Flame retardant
- Halogen free
- Norms: CE, UKCA and RoHS
- Protection class: IP65, IP67, IP68
- Cable length: 0.3 m

### Cable Cross-Section

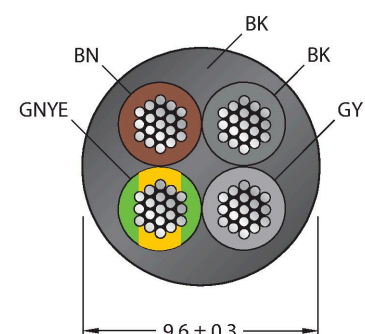

### Contact assignment

Technical data


|                                          |                              |
|------------------------------------------|------------------------------|
| Cable jacket                             | PUR, Black                   |
| Core insulation                          | PP                           |
| Core cross-section                       | 4 x 1.5 mm <sup>2</sup>      |
| Core colors                              | BN, BK, GY, GN/YE            |
| Electrical properties at +20 °C          |                              |
| Rated voltage                            | 600 V                        |
| Current                                  | 12 A                         |
| Mechanical and chemical properties       |                              |
| Bending radius (stationary installation) | ≥ 4 x Ø                      |
| Bending radius (flexible use)            | ≥ 8 x Ø                      |
| Bending cycles                           | ≥ 8 million                  |
| Admissible acceleration                  | max. 5 m/s <sup>2</sup>      |
| Admissible travel path, horizontal       | 5 m (at 5 m/s <sup>2</sup> ) |
| Torsional stress                         | ± 270 °/m                    |
| Ambient temperature (fixed)              | -40...+80 °C                 |
| Ambient temperature (mobile)             | -30...+80 °C                 |
| Ambient temperature (drag chain)         | -25...+60 °C                 |
| Qualified for drag chain use             | yes                          |
| Halogen-free                             | yes                          |
| Oil-resistant                            | yes                          |
| Flame-retardant                          | yes                          |



Circuit Diagram



Derating Curve

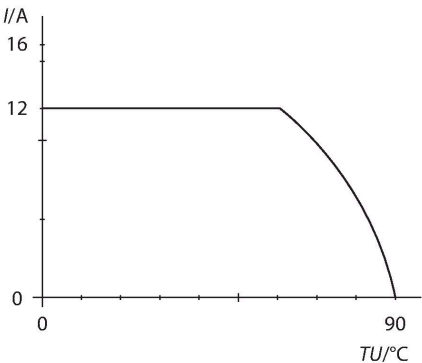

Accessories

| Dimension drawing | Type                  | ID        |                                                                                                                                                                            |
|-------------------|-----------------------|-----------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
|                   | LABEL-HOLDER-FLEX-PVC | 100048170 | PVC label holder for identification of extension cables (TEL/TXL product series); for cable diameters: min. 5 mm; dimensions 4 x 18 mm; delivery unit: 50 pcs. per package |
|                   | VH2-M12S-M4-2F4       | 100028588 | Small h-splitter, M12 Power, S-coded, 3-pin + PE                                                                                                                           |
|                   | VH3-M12S-M4-3F4       | 100028592 | Large H-splitter, M12 Power, S-coded, 3-pin + PE                                                                                                                           |
|                   | VT2-M12S-M4-2F4       | 100028580 | T-splitter, M12 Power, S-coded, 3-pin + PE                                                                                                                                 |