


FW-ERKSM0414-PL-P-0611

Field-Wireable Connector – M12 Power

Female Connector M12 × 1, Straight

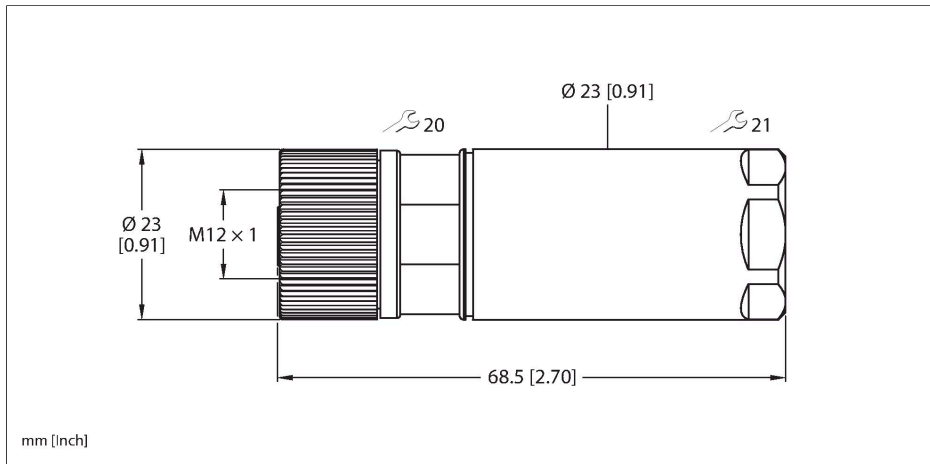

Technical data

Type	FW-ERKSM0414-PL-P-0611
ID	100045547
Connector A	Female, M12 × 1, Straight, L-coded
Number of pins	4
Contacts	Brass, CuZn, Gold-plated
Contact carriers	Plastic, PA UL94-V0, Black
Connector body	Brass, Nickel-plated, Gray
Coupling nut/screw	Brass, CuZn-Ni, Nickel-plated
Seal	Plastic, FPM/FKM
External diameter of the cable	6...11 mm
Core cross-section/Clamping ability	0.75...2.5 mm ²
Connection mode	Push-in connection
Mechanical lifespan	> 100 Mating cycles
Protection class	IP67, (screwed together)
Electrical properties at +20 °C	
Rated voltage	63 V _{DC}
Current	16 A
Mechanical and chemical properties	
Ambient temperature (fixed)	-40...+85 °C

Features



- L-coding
- Metal coupling nut
- Push-in connection
- 4-pin
- Cable feedthrough: 6.0...11.0 mm
- Shieldable
- Terminal capacity:
 - Max. 1.5 mm² or 16 AWG (without cable end sleeve)
 - Max. 2.5 mm² or 14 AWG (without cable end sleeve)

Contact assignment

