


FW-MWKPM0514-P-S-0810
Field-Wireable Connector
7/8" Female Connector, Angled



Technical data

Type	FW-MWKPM0514-P-S-0810
ID	100048528
Connector A	Female, 7/8"-16 UN, Angled
Number of pins	5
Contacts	Metal, CuZn, Gold-plated
Contact carriers	Plastic, PUR, Black
Connector body	Plastic, PBT, Black
Coupling nut/screw	Die-cast Zinc, GD-Zn, Nickel-plated
Seal	Plastic, NBR
External diameter of the cable	8...10 mm
Core cross-section/Clamping ability	0.5...2.5 mm ²
Connection mode	Screw/clamp connection
Mechanical lifespan	> 50 Mating cycles
Pollution degree	3
Protection class	IP67, Only in screwed condition
Electrical properties at +20 °C	
Rated voltage	600 V
Current	9 A
Mechanical and chemical properties	
Ambient temperature (fixed)	-25...+85 °C

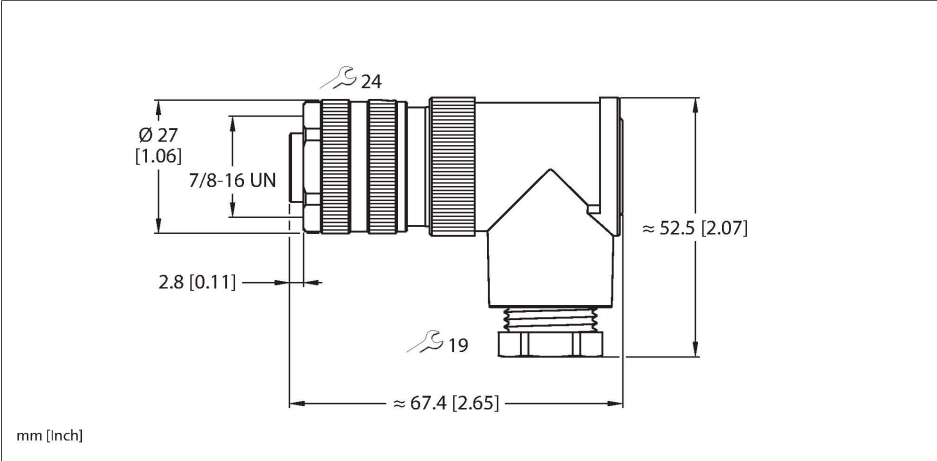

Features



- For use in DeviceNet and CANopen applications as well as for power supply
- Screw terminal connection
- 5-pin

Contact assignment

