


Accessories
Shaft Coupling Bellows Coupling
For Solid Shaft Encoders
RA-BC-20-12-12

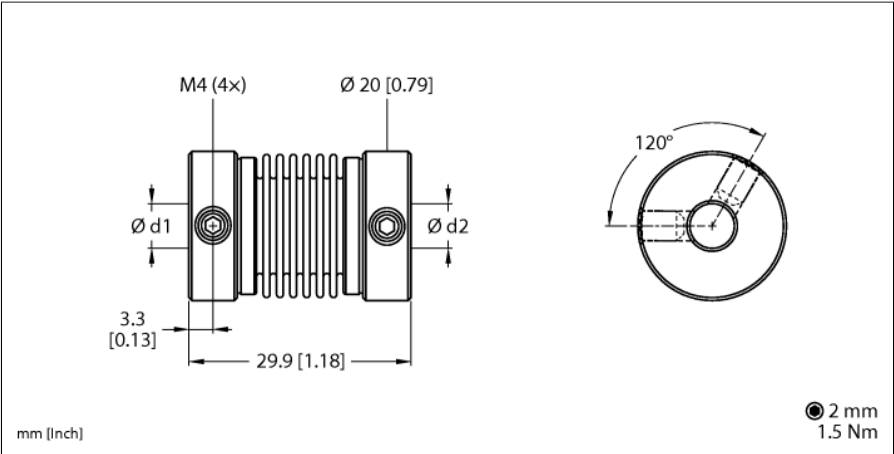

Type	RA-BC-20-12-12
ID	100048784
Max. rotational speed	10,000 rpm
Ambient temperature	-40...+140 °C

Bellows coupling with aluminum hub Ø 20 mm
Max. torque: 120 Ncm
Max. shaft offset:
Radial: ±0.25 mm
Axial: ±0.4 mm
Angular: ±4°
Torsion spring stiffness: 150 Nm/wheel
Radial spring stiffness: 25 N/mm
Moment of inertia: 8 gcm²
Receptacle material: anodized aluminum
Bellows material: stainless steel
Bore diameter d1 = 12 mm, d2 = 12 mm