


# LEDBLA1160XD6-XQ

## Vision System – Linear Area Light

### Features


- High-Intensity
- Protection class: IP50
- Color: blue
- Power supply: 24 VDC
- M12 x 1 male

### Wiring diagram

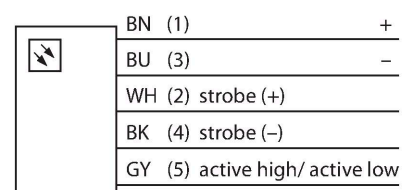

### Functional principle

High-intense illumination of large areas at long distances.

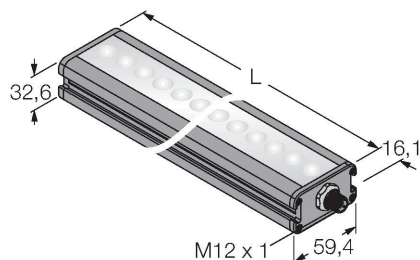

### Technical data

Type	LEDBLA1160XD6-XQ
ID	3013547
<b>Signal and display data</b>	
Purpose	Image processing
Function	Linear light
Light type	Blue
Wavelength	465...485 nm
Beam angle	6.5°
LED service life (L70)	50000 h
Features of color 1	Blue
Special features	Wash down
<b>Electrical data</b>	
Operating voltage	24 VDC
DC rated operational current	≤ 4000 mA
Max. current consumption per color	4000 mA
<b>Mechanical data</b>	
Design	Rectangular
Dimensions	1189.5 x 59.4 x 32.6 mm
Housing material	Metal, Anodized AL
Window material	Plastic, diffuse
Electrical connection	Connector, M12 × 1, PVC
Number of cores	5
Ambient temperature	0...+50 °C
Protection class	IP50
<b>Tests/approvals</b>	
Approvals	CE, cULus listed

