
 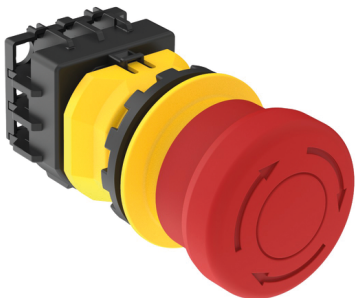


SSA-EB1P-02
Safety Technology – E-stop Button



Technical data

Type	SSA-EB1P-02
ID	3042201
Function	E-stop button, unlit
Light type	Red
Rated insulation voltage	250 V
Conventional thermal current	5 A
Impulse withstand voltage	2.5 kV
Protection class	II
Design	Rectangular
Housing material	Plastic, PC
Electrical connection	Screw terminal connection, Removable screw terminals
Ambient temperature	-25...+55 °C
Protection class	IP65
Tests/approvals	
Vibration resistance	10 to 500 Hz, 0.35 mm amplitude, 50 g acceleration
Shock resistance	15 g (11 ms)
Approvals	CE, cULus

Features

- Emergency stop button
- Mounting the console for 30-mm mounting hole
- 2 NC contacts
- 40-mm actuator
- Push and turn operation for emergency stop/release