


AT-GM-13A

Safety Relay

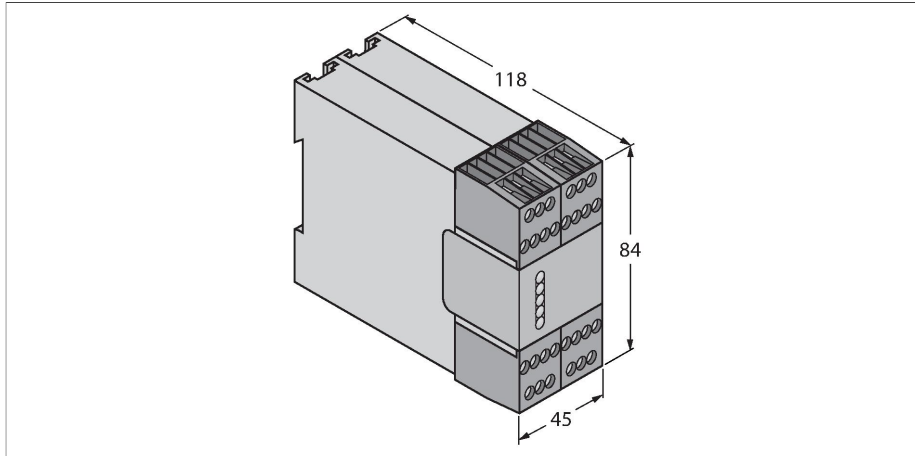

Features

- Safety category 4 acc.to ISO 13849-1 (EN 954-1)
- Operating voltage 24 VDC $\pm 15\%$
- Protection class IP20

Technical data

Type	AT-GM-13A
ID	3066089
Function	Safety relay
Operating voltage	21...28 VDC
Design	Terminal chamber
Dimensions	118 x 22.5 x 84 mm
Housing material	Plastic, PC
Electrical connection	Removable terminal block, reverse polarity protected, screw connection
Ambient temperature	0...+50 °C
Relative humidity	0...90 %
Protection class	IP20
Power-on indication	LED, Green
Switching state	LED, Green
MTTF	11 years acc. to SN 29500 (Ed. 99) 40 °C