


T8LGRXPQP


LED Indicator – Beacon

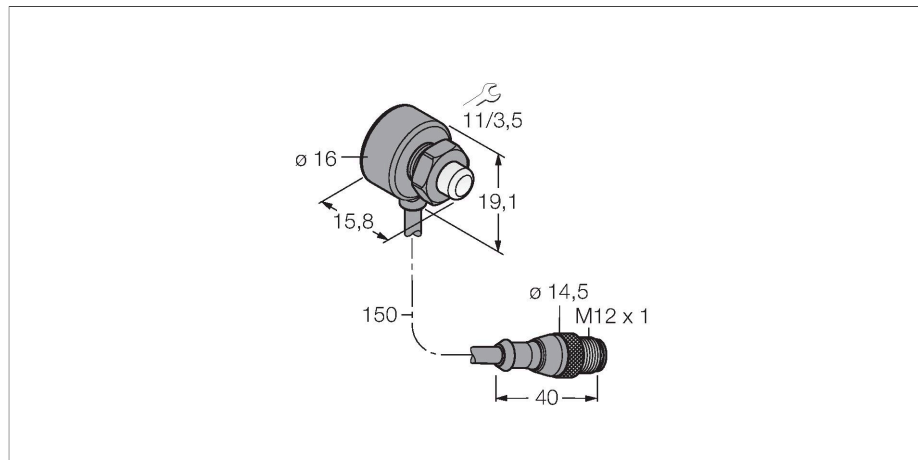

Features

- LED
- Individually controllable
- Mechanical screw-in thread M18x1
- Protection class IP67
- Multicolor: Green (COL 1) / Red (COL 2)
- Cable with male end M12 x 1
- Operating voltage 10...30 VDC

Wiring diagram

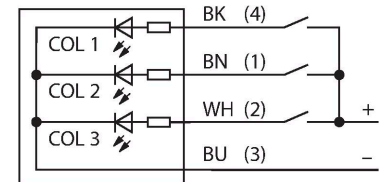

Technical data

Type	T8LGRXPQP
ID	3076420
Signal and display data	
Purpose	LED indicator light
Function	Spotlight
Light type	Green Red
Dimmable	No
Features of color 1	Green, Permanently on
Features of color 2	Red
Electrical data	
Operating voltage	10...30 VDC
DC rated operational current	≤ 20 mA
Max. current consumption per color	20 mA
Input type	PNP
Response time typical	< 1 ms
Mechanical data	
Cascadable	No
Design	Threaded barrel, T8L
Dimensions	Ø 19.1 x 15.8 mm
Housing material	Plastic, ABS/Polycarbonate, Black
Window material	Thermoplastic, diffuse
Electrical connection	Cable with connector, M12 x 1, 0.15 m, PVC
Number of cores	4
Ambient temperature	-40...+50 °C
Protection class	IP67

Technical data

Tests/approvals

MTTF 39 years acc. to SN 29500 (Ed. 99) 40 °C


Approvals CE

Accessories

SMB8MM

3067363

Mounting bracket, material VA 1.4401, for T8 or T8L series

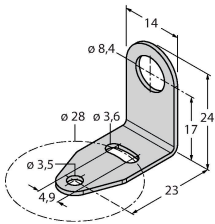

Accessories

Dimension drawing	Type	ID	
<p>Technical drawing of a straight connection cable with dimensions: 14 (connector width), 11.5 (connector length), 42 (cable length), 50 (cable length), 5 (cable length).</p>	RKC4.4T-2/TEL	6625013	Connection cable, M12 female connector, straight, 4-pin, cable length: 2 m, jacket material: PVC, black; cULus approval
<p>Technical drawing of an angled connection cable with dimensions: 14 (connector width), 26.5 (connector length), 32 (cable length), 50 (cable length), 5 (cable length).</p>	WKC4.4T-2/TEL	6625025	Connection cable, M12 female connector, angled, 4-pin, cable length: 2 m, jacket material: PVC, black; cULus approval