


LCF06LEVMP

Vision Systems – C-mount Lens

Features

- With focus and iris lock
- For VE Smart Camera
- Focal distance 6 mm
- Minimum operating distance: 77 mm
- Minimum view field: 55 × 41 mm
- Format: 1/1.8"

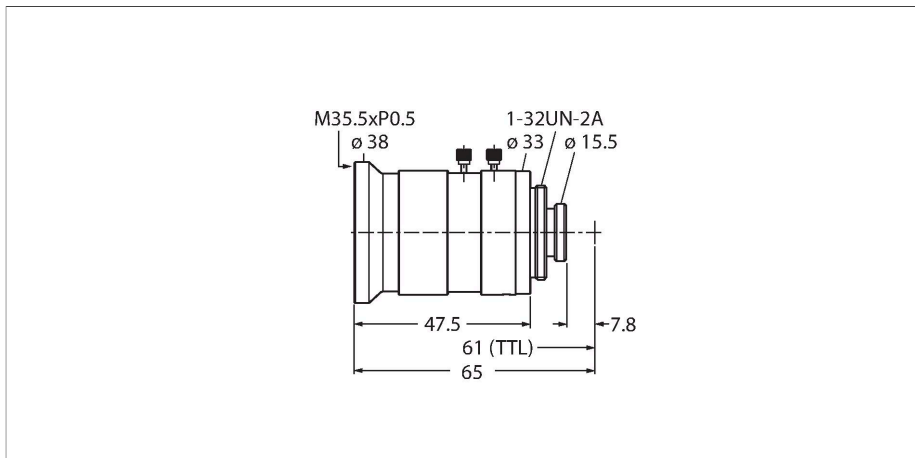

Technical data

Type	LCF06LEVMP
ID	3097345
Resolution	1600 x 1200 Pixels
Lens format	1 1 8
Minimum opening size	1,6 Megapixels
Brennweite	6 mm
Special features	Adjustable orifice Adjustable focus Closing orifice Fixed focus

Accessories

Dimension drawing	Type	ID	
Kein Maßbild vorhanden/ No dimension drawing available	FLTPR032-27	3084797	Polarization filter, 27 mm diameter suitable for LCFxxLEVMP lenses
Kein Maßbild vorhanden/ No dimension drawing available	FLTl850-27	3097532	Bandpass filter infrared, 27 mm diameter suitable for LCFxxLEVMP lenses
Kein Maßbild vorhanden/ No dimension drawing available	FLTR660-27	3097531	Bandpass filter dark red, 27 mm diameter suitable for LCFxxLEVMP lenses
Kein Maßbild vorhanden/ No dimension drawing available	FLTR635-27	3097530	Bandpass filter red, 27 mm diameter suitable for LCFxxLEVMP lenses
Kein Maßbild vorhanden/ No dimension drawing available	FLTG525-27	3097529	Bandpass filter green, 27 mm diameter suitable for LCFxxLEVMP lenses