



Bus termination resistor RSSW45-PDP-TR

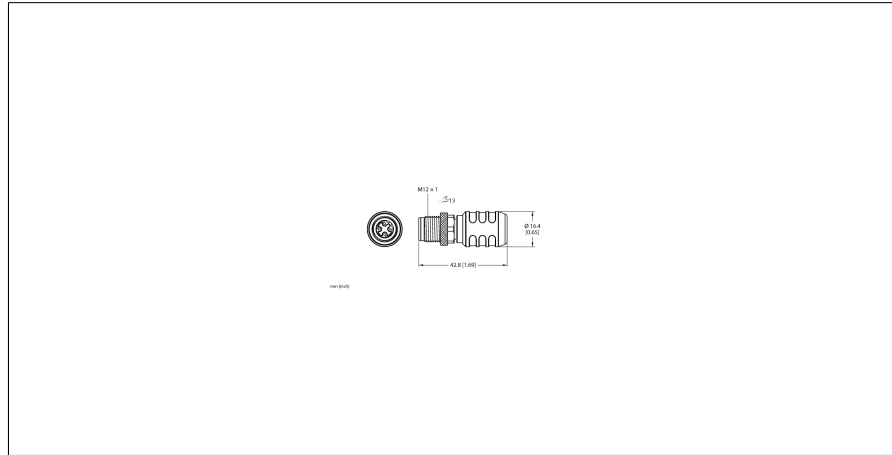

- M12 × 1 male, 4-pin, B-coded
- For use in PROFIBUS-DP applications
- Protection class: IP65, IP67, IP68 (screwed together)

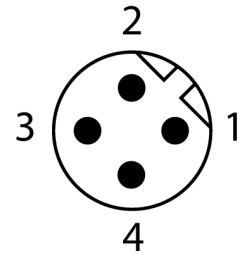

Type	RSSW45-PDP-TR
ID	6601590
Connector A	Male, M12 × 1, Straight, B-coded
Number of Pins	4
Contact carriers	Plastic, TPU, Purple
Connector body	Plastic, TPU, Black
Coupling nut/screw	Brass, CuZn, Nickel-plated
Mechanical lifespan	> 100 Mating cycles
Pollution degree	3
Protection class	IP65, IP67, IP68, (screwed together)
Network protocol	PROFIBUS-DP
Electrical properties at +20 °C	
Rated voltage	60V
Current	4AA
Insulation resistance	≥ 10 ⁸ Ω
Mechanical and chemical properties	
Ambient temperature range (stationary)	-30...+90°C

