


RKEV-CC

End Cap M12

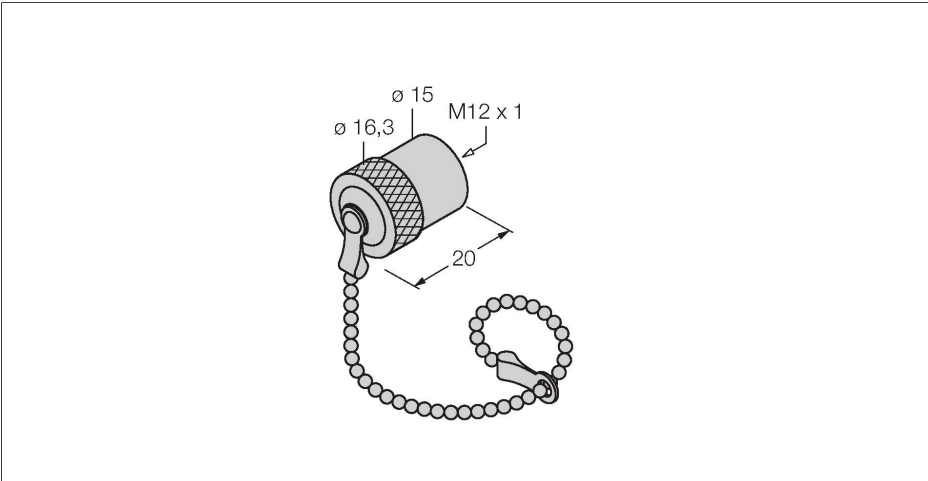

Features

- M12 × 1 end cap, stainless steel
- Female connector
- Oil resistant
- IP67 acc. to IEC 60529/ EN 60529 and NE-MA 1, 3, 4, 6P
- With fastening chain, approx. 150 mm

Technical data

Type	RKEV-CC
ID	6604175
Mechanical and chemical properties	
Ambient temperature range (In motion)	-40...+70 °C