

Cable-PDP-52-100M


Power Supply Cable/PUR – Bulk Cable

Features



- Power cable: 5 x 1.5 mm²
- Jacket material: PUR, color: gray
- Jacket diameter: 8.5 mm
- Suitable for drag chain use
- Oil-resistant and flame-retardant
- Halogen-free
- Cable length: 100 m

Cable Cross-Section

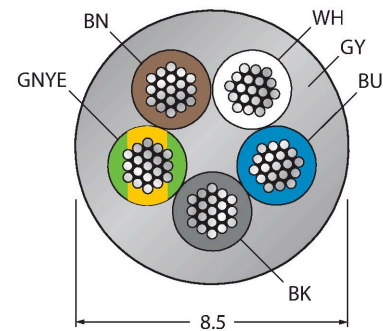

Technical data

Type	Cable-PDP-52-100M
ID	6604716
Cable diameter	Ø 8.5 mm +0.30
Cable length	100 m
Cable jacket	PUR, Gray
Shielding	no
Core insulation	PP
Core cross-section	5 x 1.5 mm ²
Arrangement of strands	40 x 0.15 mm
Core cross-section	1.5 mm ²
Core colors	BN, WH, BU, BK, GNYE
Electrical properties at +20 °C	
Rated voltage	240 V
Test voltage	2000 V
Current	5.3 A
Mechanical and chemical properties	
Ambient temperature (fixed)	-40...+90 °C
Ambient temperature (mobile)	0...+90 °C
Qualified for drag chain use	yes
Halogen-free	yes
Oil-resistant	yes
Flame-retardant	yes