


# RKC4.221T-10-RSC4.221T/TEB

## Actuator and Sensor Cable, PVC – Extension Cable



### Features

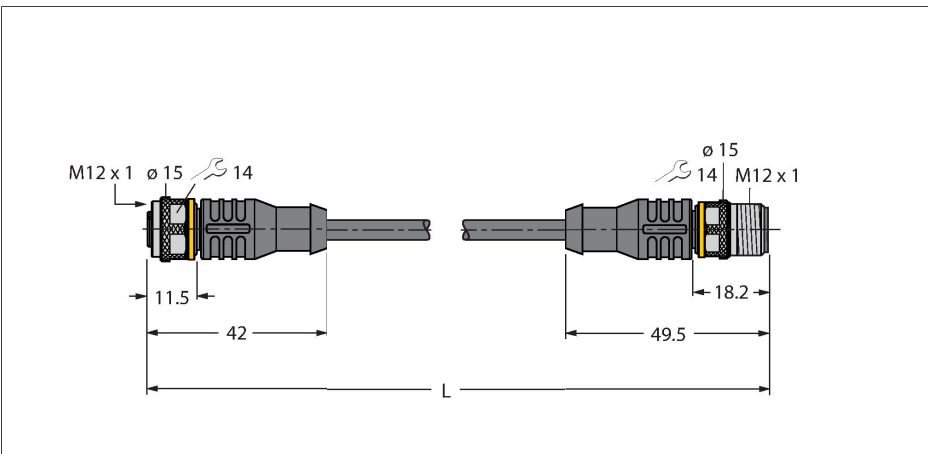


- Female M12, straight, 2-pin
- Male M12, straight, 2-pin
- Jacket material: PVC
- Jacket color: blue
- Flame retardant
- Resistant to chemicals and oils
- Resistant to microbes and hydrolysis
- LABS free
- Protection class: IP67, IP69K
- Cable length: 10 m


### Technical data

|                              |                                         |
|------------------------------|-----------------------------------------|
| Type                         | RKC4.221T-10-RSC4.221T/TEB              |
| ID                           | 6628443                                 |
| Connector A                  | Female, M12 × 1, Straight, A-coded      |
| Number of pins               | 2                                       |
| Contacts                     | Brass, CuZn, Gold-plated                |
| Contact carriers             | Plastic, TPU, Black                     |
| Connector body               | Plastic, TPU, Black                     |
| Coupling nut/screw           | Brass, CuZn, Nickel-plated              |
| Seal                         | Plastic, FPM/FKM                        |
| Mechanical lifespan          | > 100 Mating cycles                     |
| Pollution degree             | 3                                       |
| Protection class             | IP67, IP69K, Only in screwed condition  |
| Connector B                  | Male, M12 × 1, Straight, A-coded        |
| Number of Pins               | 2                                       |
| Contacts                     | Brass, CuZn, Gold-plated                |
| Contact carriers             | Plastic, TPU, Black                     |
| Connector body               | Plastic, TPU, Black                     |
| Coupling nut/retaining screw | Brass, CuZn, Nickel-plated              |
| Mechanical life              | > 100 Mating cycles                     |
| Pollution degree             | 3                                       |
| Protection class             | IP67, IP69K, Only when screwed together |
| Cable                        |                                         |
| Cable diameter               | Ø 4.4 mm ±0.20                          |
| Cable length                 | 10 m                                    |
| Cable jacket                 | PVC, Blue                               |
| Core insulation              | PVC                                     |
| Core cross-section           | 2 x 0.5 mm <sup>2</sup>                 |


### Cable Cross-Section

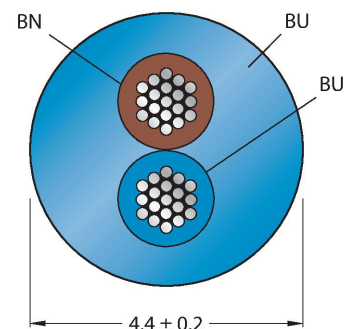

### Contact assignment

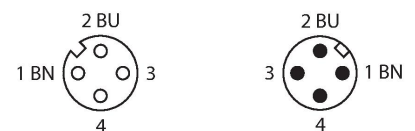

### Circuit Diagram

 


Technical data

|                                          |               |
|------------------------------------------|---------------|
| Arrangement of strands                   | 64 x 0.1 mm   |
| Core colors                              | BN, BU        |
| Electrical properties at +20 °C          |               |
| Rated voltage                            | 250 V         |
| Test voltage                             | 2000 V        |
| Current                                  | 4 A           |
| Insulation resistance                    | > 30.5 MΩ/km  |
| forward resistance                       | max. 57 Ω/km  |
| Nom. capacitance                         | 0.89 pF/m     |
| Nom. Inductance                          | 1.25 mH/km    |
| Mechanical and chemical properties       |               |
| Bending radius (stationary installation) | ≥ 5 x Ø       |
| Bending radius (flexible use)            | ≥ 10 x Ø      |
| Ambient temperature (fixed)              | -40...+105 °C |
| Ambient temperature (mobile)             | -5...+80 °C   |
| Approvals                                | cULus         |

Accessories

|                                                                                                                       |         |                                                                                                                                         |         |
|-----------------------------------------------------------------------------------------------------------------------|---------|-----------------------------------------------------------------------------------------------------------------------------------------|---------|
| TORQUE-WRENCH-SET-AS                                                                                                  | 6936170 | BLANK-LABEL-FOR-CORDSETS-TEL-TXL                                                                                                        | 6936206 |
| Torque wrench set; handles with adjustable torque 0.4-1.0 Nm, torque wrench for M8 (SW9), fork wrench for M12 (SW 14) |         | Label for TEL and TXL cables, length: 18 mm, height: 4 mm, material: polycarbonate (PC), color: white, halogen-free and flame-retardant |         |

 

Accessories

|                                                                                     |                       |           |                                                                                                                                                                            |
|-------------------------------------------------------------------------------------|-----------------------|-----------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Dimension drawing                                                                   | Type                  | ID        |                                                                                                                                                                            |
|  | LABEL-HOLDER-FLEX-PVC | 100048170 | PVC label holder for identification of extension cables (TEL/TXL product series); for cable diameters: min. 5 mm; dimensions 4 × 18 mm; delivery unit: 50 pcs. per package |