


AD-FSM4.211-FSM4.211

Adapter

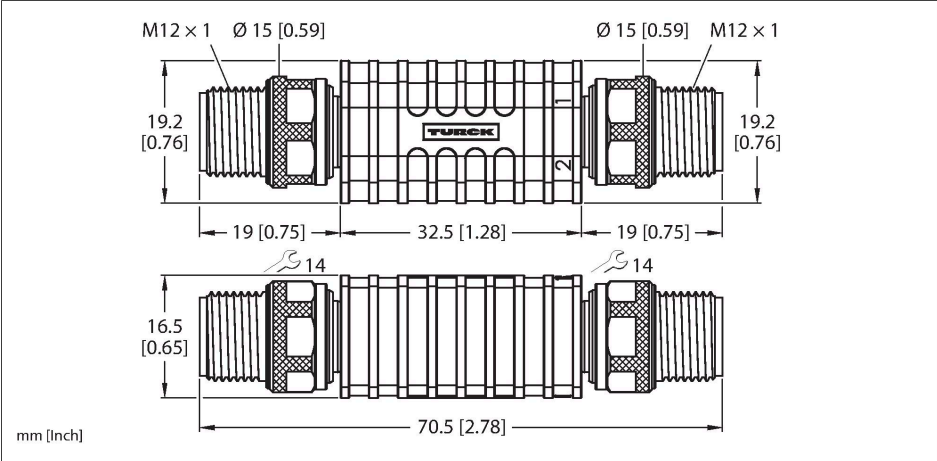

Technical data

Type	AD-FSM4.211-FSM4.211
ID	6631954
Connector A	Male, M12 × 1, Straight
Number of pins	4
Contacts	Brass, CuZn, Gold-plated
Contact carriers	Plastic, TPU, Black
Connector body	Plastic, TPU, Black
Coupling nut/screw	Brass, CuZn, Nickel-plated
Tightening torque (range)	0.6 ... 0.8 Nm (observe max. torque of mating connector!)
Mechanical lifespan	> 100 Mating cycles
Protection class	IP67, (screwed together)
Connector B	Male, M12 × 1, Straight
Number of Pins	4
Contacts	Brass, CuZn, Gold-plated
Contact carriers	Plastic, TPU, Black
Connector body	Plastic, TPU, Black
Coupling nut/retaining screw	Brass, CuZn, Nickel-plated
Tightening torque	0.6 ... 0.8 Nm (observe max. torque of mating connector!)
Mechanical life	> 100 Mating cycles
Protection class	IP67, (Screwed together)
Electrical properties at +20 °C	
Rated voltage	250 V
Current	4 A

Features




- M12 male – M12 male
- Pin 2 connected with 2 and 4 with 4
- Pin 1 and pin 3 not assigned
- RoHS-compliant
- Protection class: IP67

Contact assignment



Circuit Diagram

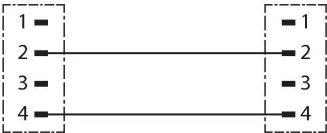

Technical data

Mechanical and chemical properties

Ambient temperature (fixed)	-30...+80 °C
-----------------------------	--------------
