


AD-FKM4-FSM4 Adapters

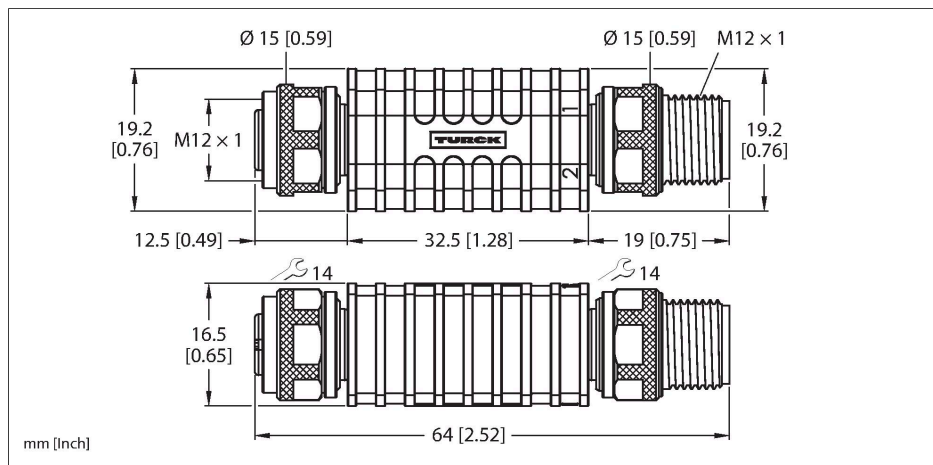


Technical data

Type	AD-FKM4-FSM4
ID	6633869
Connector A	Female, M12 × 1, Straight
Number of Pins	3
Contacts	Brass, CuZn, Gold-plated
Contact carriers	Plastic, TPU, Black
Connector body	Plastic, TPU, Black
Coupling nut/screw	Brass, CuZn, Nickel-plated
Tightening torque (range)	0.6 ... 0.8 Nm (observe max. torque of mating connector!)
Mechanical lifespan	> 100 Mating cycles
Protection class	IP67, (screwed together)
Connector B	Male, M12 × 1, Straight
Number of pins	3
Contacts	Brass, CuZn, Gold-plated
Contact carriers	Plastic, TPU, Black
Connector body	Plastic, TPU, Black
Coupling nut/retaining screw	Brass, CuZn, Nickel-plated
Tightening torque	0.6 ... 0.8 Nm (observe max. torque of mating connector!)
Mechanical life	> 100 Mating cycles
Protection class	IP67, (Screwed together)
Electrical properties at +20 °C	
Rated voltage	250 V
Current	4 A


Features

- M12 female – M12 male, 3-pin
- RoHS-compliant
- Protection class: IP67

 Contact assignment



Circuit Diagram

 

Technical data

Mechanical and chemical properties

Ambient temperature range (stationary) -30...+80 °C
