


# compact fieldbus station for AS-interface

## 4 Inputs, 4 Outputs

### FAS4-CSG44-A

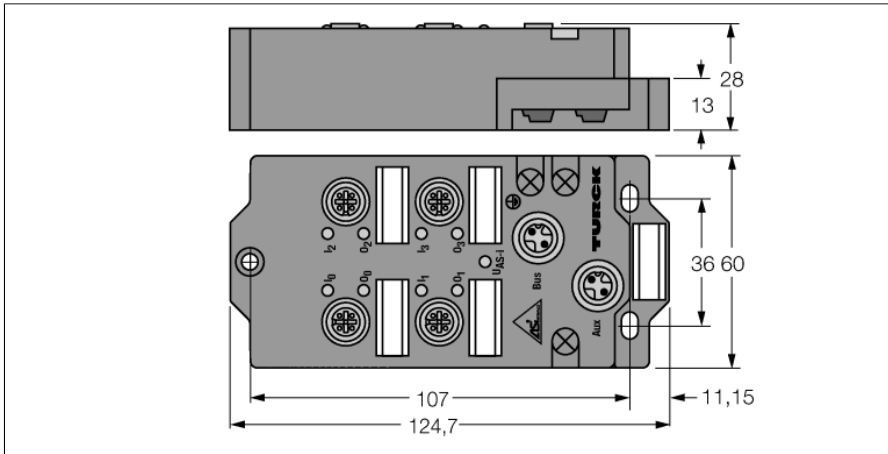

- Bus connected via AS-interface flat cable or male M12 x 1
- Field devices connected via male M12 x 1
- AS-i specification V2.1
- Short-circuit diagnostics
- Cast housing
- Protection class IP67
- Address range 1...31
- 4 inputs PNP
- 4 outputs PNP
- 24 VDC
- Additional power supply of the outputs

Type	FAS4-CSG44-A
ID	6821325

Number of channels	4/4
Operating / load voltage	18...31 (AS-i) VDC
internal power consumption	<20 mA plus I/O supply

<b>Inputs</b>	
Number of channels	4
Low level signal current	<2 mA at 24 VDC
High level signal current	3...3.4 mA at 24 VDC
Input delay	2.5 ms
Max. input current	Total: 700 mA

 
<b>Outputs</b>	
Number of channels	4
Output current per channel	700 mA (Aux)
Short-circuit protection	yes

Fieldbus address range	1...31
Fieldbus addressing	AS-i addressing tool

LEDs Bus	I/O: green = on . red = short-circuit (outputs) AS-i green = OK . red/green = fault
----------	--


Dimensions (W x L x H)	60 x 124.7 x 28 mm
Housing material	fibre-glass reinforced Polyamide (PA6-GF30)
Mounting	4 mounting holes Ø 5,4 mm
Ambient temperature	-25...+70 °C
Protection class	IP67

#### Fieldbus



#### M12 x 1 Input/Output

 3-wire pnp sensor  
DC actuator



#### Power Supply

