


# Mounting Accessories

## Actuation kit (puck)

### BTS-DSU35-EBE1-2

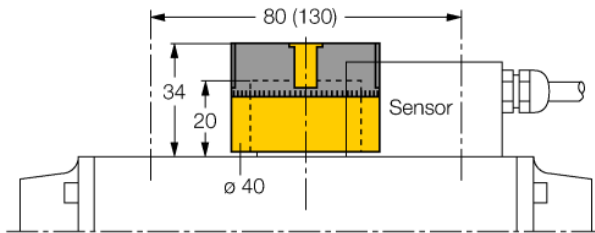

- End position damped
- End position (open/closed) infinitely adjustable in a range of 360°
- Displays rotatable by 90°
- Scale division
- Hole pattern on flange surface: 30 x 80 mm (30 x 130 mm)
- Connection shaft (shaft extension) height: 20 mm/Ø: max. 30 mm

#### General description

Dual sensors are especially designed for position detection in rotary actuators. They combine the reliability of non-contact inductive sensors with the flexibility of a modular housing system. A broad range of practice-oriented accessories ensure optimal adaption to your system.

Type	BTS-DSU35-EBE1-2
ID	6900497
Design	Accessories for dual sensor, Ni4-DSU35...
Housing material	Plastic, PP-GF30
Tightening torque	≤ 1.5 Nm
Included in delivery	2 Hex cap screw, M5 × 12, 2 pcs. D5 lock washers, 1 countersunk screw M6 × 25

