


BKV4140-0/9
Field-Wireable Connector
7/8" Female, Straight

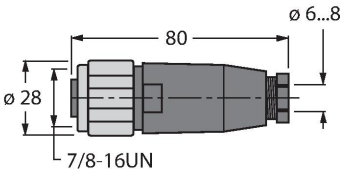

Technical data



Type	BKV4140-0/9
ID	6914543
Connector A	Female, 7/8"-16 UN, Straight
Number of pins	4
Contacts	Metal, CuZn, Gold-plated
Contact carriers	Plastic, TPU, Black
Connector body	Plastic, PA, Black
Coupling nut/screw	Stainless Steel, 1.4404, Passivated
Seal	Plastic, NBR
Screw-in thread	PG9
External diameter of the cable	6...8 mm
Core cross-section/Clamping ability	0.14...1 mm²
Connection mode	Screw/clamp connection
Mechanical lifespan	> 50 Mating cycles
Pollution degree	3
Protection class	IP67, Only in screwed condition
Network protocol	PROFIBUS-PA
Electrical properties at +20 °C	
Rated voltage	250 V
Current	9 A
Insulation resistance	≥ 10 ⁸ Ω
forward resistance	≤ 5 mΩ
Mechanical and chemical properties	
Ambient temperature (fixed)	-40...+90 °C
Ambient temperature (mobile)	-40...+90 °C

Features



- For use in PROFIBUS-PA and FOUNDATION fieldbus applications
- Screw-clamp terminal
- Stainless steel coupling nut
- 4-pin
- PG9 screw-in thread
- Cable feedthrough 6.0...8.0 mm

  Contact assignment



Headline Wiring Diagram

PROFIBUS-PA Connection FOUNDATION fieldbus connection



Technical data

Note

- We reserve the right to make technical modifications without prior notice.