


ESP3SL

Round connector M8 x 1 / Ø 8 mm – Ø 8 mm flange connector, snap-on type

 


Features

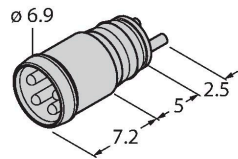

- Robust and pre-assembled flange connector
- 3-pin
- Potted, protection class IP67
- GOST-R-approved
- RoHS-compliant
- Solder contact

Contact assignment



Technical data

Type	ESP3SL
ID	6934770
Connector A	Male, Ø 8 mm
Number of pins	3
Contacts	Metal, CuZn, Gold-plated
Contact carriers	Plastic, PA, Black
Flange housing	Plastic, PA, black
Connection mode	Solder contact
Mechanical lifespan	> 100 Mating cycles
Pollution degree	3/2
Protection class	IP67, (plugged)
Rated voltage	60 V
Current	4 A
Insulation resistance	$\geq 10^9 \Omega$
Ambient temperature (fixed)	-30...+90 °C

