


PFKS3-0.2

Female Flange with Stranded Wires, Front-mounted – Female Flange with Stranded Wires, Front-mounted

 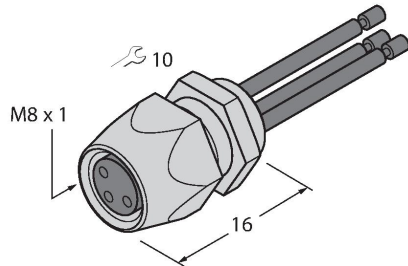


Features




- robust and pre-assembled round connector
- Degree of protection IP67
- with 0.2 m litz wire
- also available with other litz wire lengths
- Stranded wire length: 0.2 m

Contact assignment




Headline Wiring Diagram

Wiring Diagram

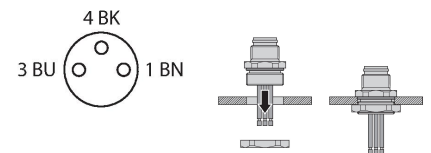

Technical data

Type	PFKS3-0.2
ID	6934785
Connector A	Female, M8 × 1, Straight
Number of pins	3
Contacts	Metal, CuZn, Gold-plated
Contact carriers	Plastic, PA, Black
Seal	Plastic, FPM/FKM
Flange housing	Brass, CuZn, Nickel-plated
Mounting type	front panel mounting
Screw-in thread seal	Plastic, NBR
Screw-in thread	M8 × 0.5
Connection mode	Wire connection
Mechanical lifespan	> 100 Mating cycles
Pollution degree	3
Protection class	IP67, (screwed together)
Cable length	0.2 m
Core insulation	PVC
Core cross-section	3 x 0.25 mm ²
Arrangement of strands	14 x 0.15 mm
Core colors	BN, BU, BK
Electrical properties at +20 °C	
Rated voltage	60 V
Current	4 A
Insulation resistance	≥ 10 ⁸ Ω
forward resistance	≤ 5 mΩ

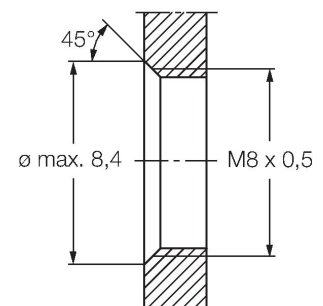

Technical data

Mechanical and chemical properties

Ambient temperature (fixed)	-30...+90 °C
Approvals	CE