


Accessories

Thermowell

For Temperature Sensors

THW-6-TRI3/4-A4-L100

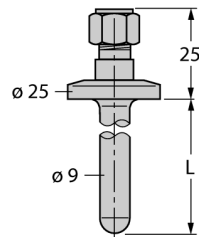

- Thermowell for mounting temperature probes
- End tip diameter 6 mm
- Process connection Tri-Clamp 3/4"
- Immersion depth 100 mm
- For use in food and pharmaceutical applications
- Surface roughness Ra > 0.8 µm

General description

Thermowells protect the probes against aggressive substances and high pressures. The probes do not come into contact with any media. They can be replaced without interrupting the process.

Type	THW-6-TRI3/4-A4-L100
ID	9910468
Temperature range	
Measuring range	-50...350 °C
	-58...662 °F
Immersion depth L	100 mm
Outer diameter	9 mm
Mechanical data	
Housing material	Stainless steel
Internal diameter	6.2 mm
Process connection	Tri-Clamp 3/4"
Pressure resistance	40 bar
Max. tightening torque of housing nut	100 Nm