


Actuator and Sensor T-Splitter


T-Splitter

RSM-2RKM 50

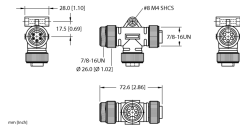

- 7/8" minifast
- 7/8" male connector, straight, 5-pin
- 2 × 7/8" female connector, straight, 5-pin

Type	RSM-2RKM 50
ID	U2109-9
Distributed I/O Housing	T-splitter, 2-port Plastic, TPU, Yellow
Connector A	Male, 7/8"-16 UN
Number of Pins	5
Contact carriers	Plastic, TPU, Yellow
Coupling nut/screw	Brass, CuZn, Nickel-plated
Mechanical lifespan	> 100 Mating cycles
Pollution degree	3
Protection class	IP67, Only in screwed condition NEMA: 1, 3, 4, 6P
Connector B	2 x Female, 7/8"-16 UN
Number of pins	5 pins
Contact carriers	Plastic, TPU, Yellow
Coupling nut/retaining screw	Brass, CuZn, Nickel-plated
Mechanical life	> 100 Mating cycles
Pollution degree	3
Protection class	IP67, Only when screwed together NEMA: 1, 3, 4, 6P
Electrical properties at +20 °C	
Rated voltage	250V
Current	9AA
Insulation resistance	≥ 10 ⁸ Ω
forward resistance	≤ 5 mΩ
Mechanical and chemical properties	
Ambient temperature range (stationary)	-40...+80°C
Ambient temperature range (In motion)	-40...+80°C
Note	- We reserve the right to make technical modifications without prior notice.

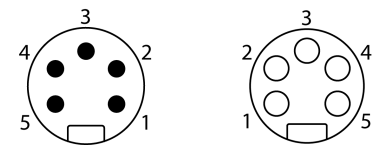

Circuit Diagram

