


Conector cableable en campo

Conector hembra, recto


B23171-8.5

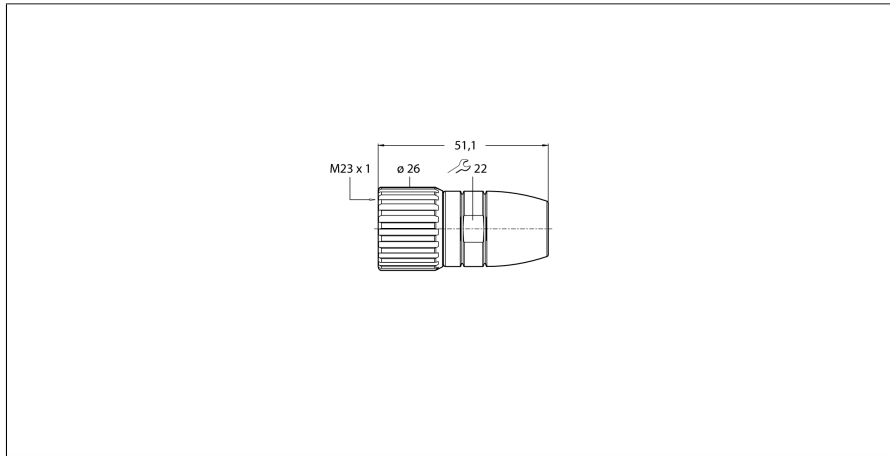

- Con contactos engastables (los contactos no están incluidos en la entrega; estos se pueden solicitar con el número 6900272)
- 7 polos

Tipo	B23171-8.5
N.º de ID	6900270
Conector A	
Conector A	Conector hembra, M23 × 1, Recto
Número de polos	7
Soporte del contacto	Plástico, PA
Empuñadura	Fundición inyectada de zinc, GD-Zn, niquelado
Modo de conexión	Conexión de crimpado
Vida útil de funcionamiento mecánico	> 50 Ciclos de acoplamiento
Grado de protección	IP67, (atornillado)
Propiedades eléctricas a +20 °C	
Resistencia de aislamiento	≥ 10 ⁸ Ω
Propiedades químicas y mecánicas	
En reposo	-40...+85°C

Accesorios

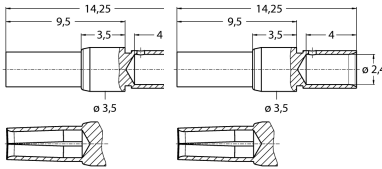Modelo	N° de identificación		Dibujo acotado
B23-0001	6900272	Contacto de engarzado hembra (no principal) para conectores M23 macho BS23171-8.5 (6900273) y BS23271-8.5 (6900274); sección transversal de la conexión: 1,5-2,5 mm ²	 <p>The drawing shows two views of a female contact pin. The top view is a side view with dimensions: a total length of 14,25 mm, a distance of 9,5 mm from the left end to the start of the contact, a contact length of 3,5 mm, and a distance of 4 mm from the end of the contact to the right end. The diameter is indicated as $\varnothing 3,5$. The bottom view is a cross-sectional view showing the internal structure of the contact, with a diameter of $\varnothing 3,5$ and a depth of 2,4 mm.</p>