



Voedingskabel  
TPE-kabelmantel  
RSM RKM 461-2M/S3059



|                        |                                    |
|------------------------|------------------------------------|
| Type                   | RSM RKM 461-2M/S3059               |
| Identnr.               | U-31034                            |
| Connector A            | Connector, 7/8"-16 UN, Recht       |
| Aantal polen           | 4                                  |
| Contacten              | Messing, CuZn, Verguld             |
| Contactdrager          | Kunststof, TPU, Geel               |
| Greep                  | Kunststof, TPU, Geel               |
| Wartelmoer/-bout       | Messing, CuZn, Vernikkeld          |
| Beschermingsklasse     | IP67, IP68, IP69, IP69K            |
| Mechanische levensduur | > 100 Steekcycli                   |
| Vervuilingsgraad       | 3                                  |
| Connector B            | Contraconnector, 7/8"-16 UN, Recht |
| Aantal polen           | 4                                  |
| Contacten              | Messing, CuZn, Verguld             |
| Contactdrager          | Kunststof, TPU, Geel               |
| Greep                  | Kunststof, TPU, Geel               |
| Wartelmoer/-bout       | Messing, CuZn, Vernikkeld          |
| Beschermingsklasse     | IP67, IP68, IP69, IP69K            |
| Mechanische levensduur | > 100 Steekcycli                   |
| Vervuilingsgraad       | 3                                  |
| Kabeldiameter          | Ø 9.14 mm                          |
| Kabellengte            | 2 m                                |
| Kabelmantel            | TPE, Geel                          |
| Aderisolatie           | PVC/nylon                          |
| Aderkleuren            | BN, WH, BU, GNYE                   |
| Aderdoorsnede          | 4                                  |
| Draadopbouw            | 65                                 |
| Nominale spanning      | 600 V                              |
| Stroombelastbaarheid   | 10 A                               |

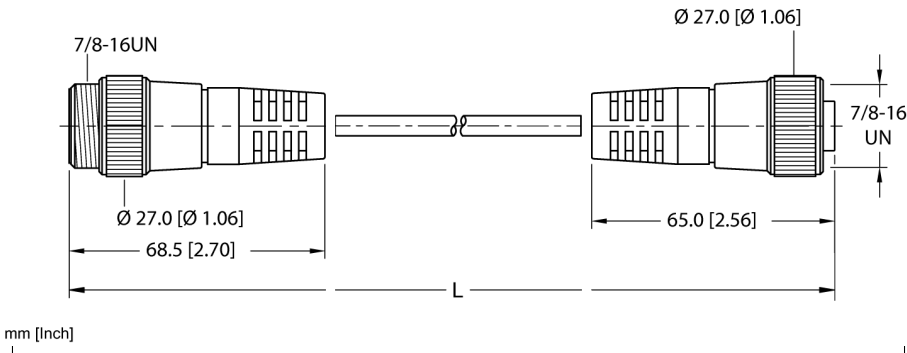

- 7/8" contraconnector, recht, 3-polig + PE
- 7/8" connector, recht, 3-polig + PE
- Mantelkleur: geel
- Kabellengte: 2,0 m
- beschermingsklasse: NEMA 1, 3, 4, 6P en IEC IP67
- 7/8"-connector, recht, 4-polig
- 7/8"-contraconnector, recht, 4-polig
- Power-Tray/Exposed Run/Direct Burial-kabel
- TPE-buitenmantel, geel, 4 × 16 AWG
- UV-bestendig
- -40 °C koude buigsterkte
- Oliebestendig
- Brandklassen: UL 1685 FT4, UL 1061, CSA FT1, CSA FT4

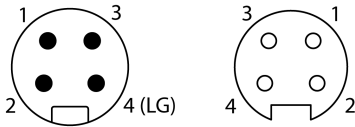

schakelplan

