



Przetwarzanie obrazu czujnik wizyjny ze zintegrowanym kontrolerem P4OR-BCBDOC

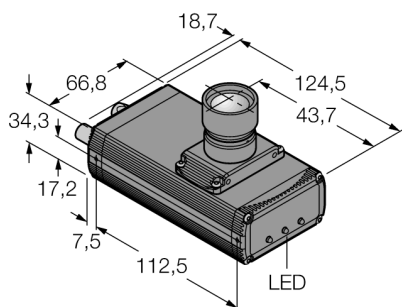

Typ	P4OR-BCBDOC
Nr kat.	3079913
Dane kamery	
Funkcja	Wykonanie wielofunkcyjne
Resolution	640 × 480 pikseli
Brennweite	8 mm
Dane elektryczne	
Napięcie robocze U _s	10...30 V DC
Prąd znamionowy DC I _s	≤ 650 mA
Protokół komunikacyjny	EtherNet/IP Modbus TCP Modbus TCP PCCC RS232
Funkcja wyjścia	Styk NO, PNP/NPN
Power on display	LED, zielony
Wskaźnik stanu przełączenia	LED, Zielony
Wskaźnik błędu	LED, czerwony
Dane mechaniczne	
Wykonanie	Prostopadłościenny, P4
Materiał obudowy	Metal, AL
Połączenie elektryczne	Złącze, M12 × 1, 12-przewodowy
Temperatura pracy	0...+50 °C
Stopień ochrony	IP20
Testy/aprobaty	
Certyfikaty	CE

- Pełny zakres funkcji, AREA, EDGE i GEO
- 1/3" CMOS, 752x480 pikseli
- 256-stopniowa skala szarości
- Universal application for extended inspection
- AREA function
- EDGE function
- GEO function
- Barcode reader
- OCR/OCV function
- Bead inspection

Schemat podłączenia

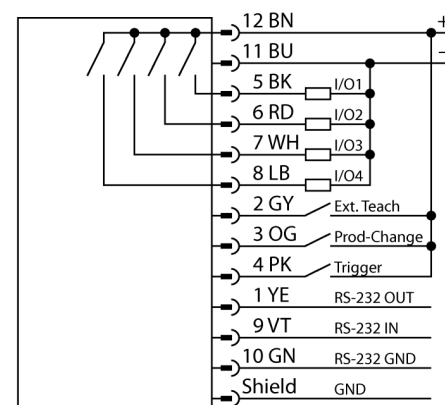

Zasada działania

The camera system PresencePLUS P4 consists of a camera with an integrated processing unit. Lens, lighting and connection cable are to be ordered separately. Freeware and firmware updates are available for download on: www.bannerengineering.com