


**Разборный штекерный разъем  
Гнездовой разъем, прямой  
B23171-8.5**

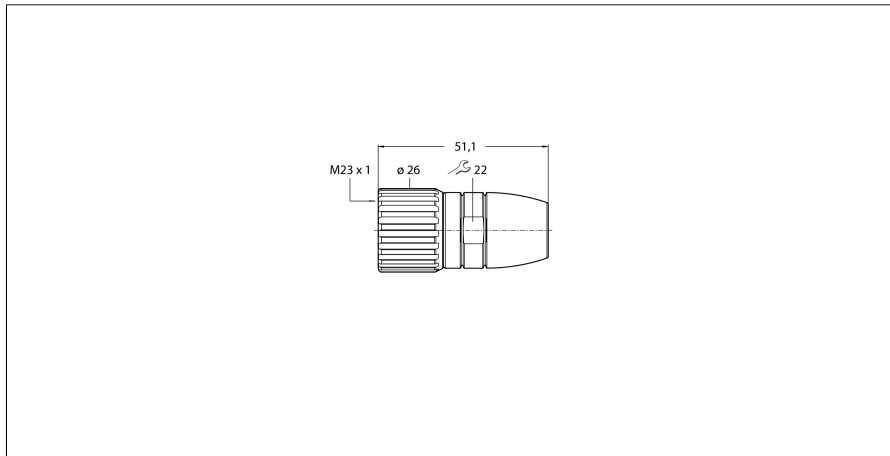

- с обжимными контактами (контакты не входят в комплект поставки; номер контактов по каталогу 6900272)
- 7-контакт.

<b>Тип</b>	B23171-8.5
<b>ID №</b>	6900270
<b>Разъем А</b>	Гнездовой разъем, M23 × 1, Прямой
Кол-во контактов	7
Подложка контактов	Пластмасса, PA
Ручка	Цинк, литье под давлением, GD-Zn, никелированный
Тип соединения	Обжимное соединение
Механический срок службы	> 50 Циклы коммутации
Класс защиты	IP67, (привинчены друг к другу)
<b>Электрические характеристики +20 °C</b>	
сопротивление изоляции	≥ 10 <sup>8</sup> Ом
<b>Механические и химические свойства</b>	
в состоянии покоя	-40°C...+85°C°C

**Разборный штекерный разъем  
Гнездовой разъем, прямой  
B23171-8.5**

**Аксессуары**

Наименование	Идент. №		Чертеж с размерами
B23-0001	6900272	Гнездовой обжимной контакт (неведущий) для штекерных разъемов M23 BS23171-8.5 (6900273) и BS23271-8.5 (6900274); поперечное сечение соединения: 1,5–2,5 мм <sup>2</sup>	<p>The drawing shows two views of the crimp contact. The top view is a side profile showing a cylindrical body with a crimped end. Dimensions are: total length 14.25 mm, distance from end to crimp 9.5 mm, crimp diameter 3.5 mm, and crimp length 4 mm. The bottom view is a cross-section showing the crimped end with a diameter of 3.5 mm and a crimp depth of 2.4 mm. Below the main views are two smaller perspective drawings of the crimped end.</p>