


# compact fieldbus station for AS-interface

 
## 4 Inputs, 3 Outputs

### FAS4-CSG43

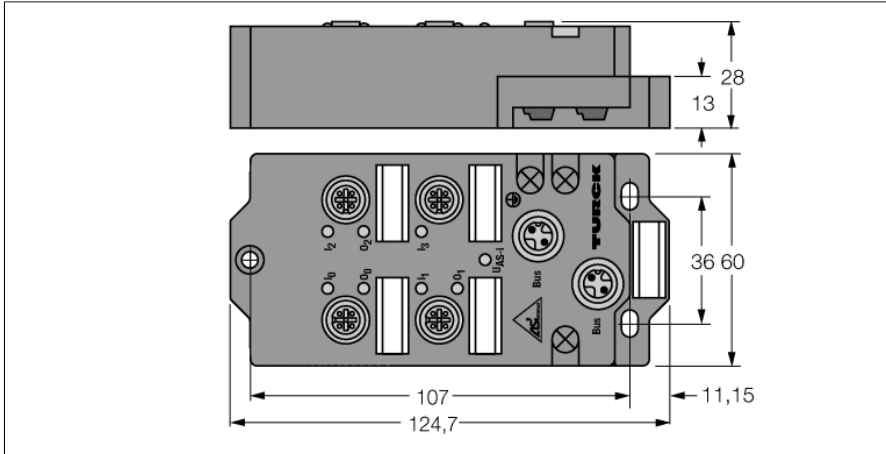


- Bus connected via AS-interface flat cable or male M12 x 1
- Field devices connected via male M12 x 1
- AS-i specification V2.1
- Short-circuit diagnostics
- Cast housing
- Protection class IP67
- Address range 1...31 A/B
- 4 inputs PNP
- 3 outputs PNP
- 24 VDC

#### Fieldbus



#### M12 x 1 Giriş/Çıkış

 3-wire pnp sensor  
DC actuator



Tip	FAS4-CSG43
Tanit. no.	6821322
Operating / load voltage	18...31 (AS-i) VDC
internal power consumption	<20 mA plus I/O supply
<b>Girişler</b>	
Number of channels	4
Düşük seviye sinyal akımı	<2 mA at 24 VDC
Yüksek seviye sinyal akımı	3...3.4 mA at 24 VDC
Giriş gecikmesi	2.5 ms
Maks. giriş akımı	Total: 400 mA
<b>Çıkışlar</b>	
Number of channels	3
Kanal başına çıkış akımı	200 mA
Kısa devre koruması	evet
Fieldbus adres aralığı	1...31 A/B
Fieldbus adresleme	AS-i addressing tool
LEDs Bus	I/O: green = on . red = short-circuit (outputs) AS-i green = OK . red/green = fault
Boyutlar (W x L x H)	60 x 124.7 x 28 mm
Housing material	fibre-glass reinforced Polyamide (PA6-GF30)
Montaj	4 mounting holes Ø 5,4 mm
Ortam sıcaklığı	-25...+70 °C
IP Derecesi	IP67