


# compact fieldbus station for AS-interface

 
## 3 Outputs

### FAS4-S0003G-A

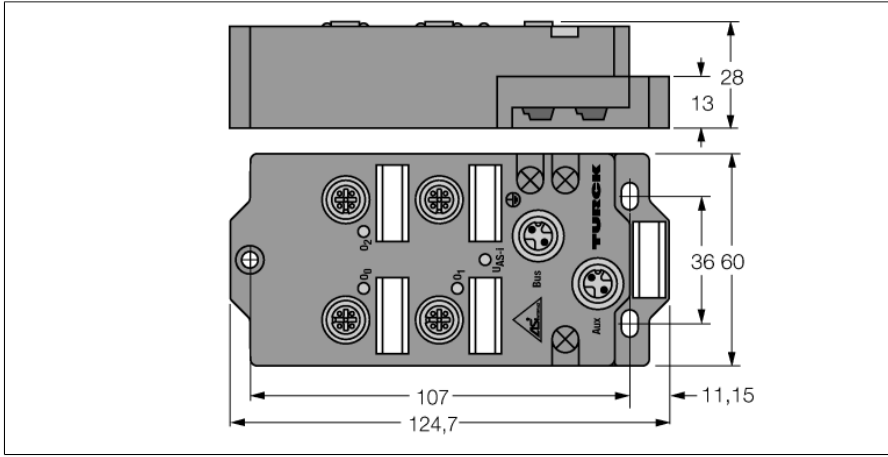


- Bus connected via AS-interface flat cable or male M12 x 1
- Field devices connected via male M12 x 1
- AS-i specification V2.1
- Short-circuit diagnostics
- Cast housing
- Protection class IP67
- Address range 1...31 A/B
- 3 outputs PNP
- 24 VDC
- Additional power supply of the outputs

#### Fieldbus




#### M12 × 1 Çıkış

 DC actuator



#### Güç Kaynağı

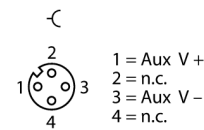

Tip	FAS4-S0003G-A
Tanit. no.	6821326
Operating / load voltage	18...31 (AS-i) VDC
internal power consumption	<20 mA plus I/O supply
<b>Çıkışlar</b>	
Number of channels	3
Kanal başına çıkış akımı	700 mA (Aux)
Kısa devre koruması	evet
Fieldbus adres aralığı	1...31 A/B
Fieldbus adresleme	AS-i addressing tool
<b>LEDs Bus</b>	I/O: green = on . red = short-circuit (outputs) AS-i green = OK . red/green = fault
Boyutlar (W x L x H)	60 x 124.7 x 28 mm
Housing material	fibre-glass reinforced Polyamide (PA6-GF30)
Montaj	4 mounting holes Ø 5,4 mm
Ortam sıcaklığı	-25...+70 °C
IP Derecesi	IP67