


compact fieldbus station for AS-interface

2 Inputs, 2 Outputs


FAS4-S0202G-A

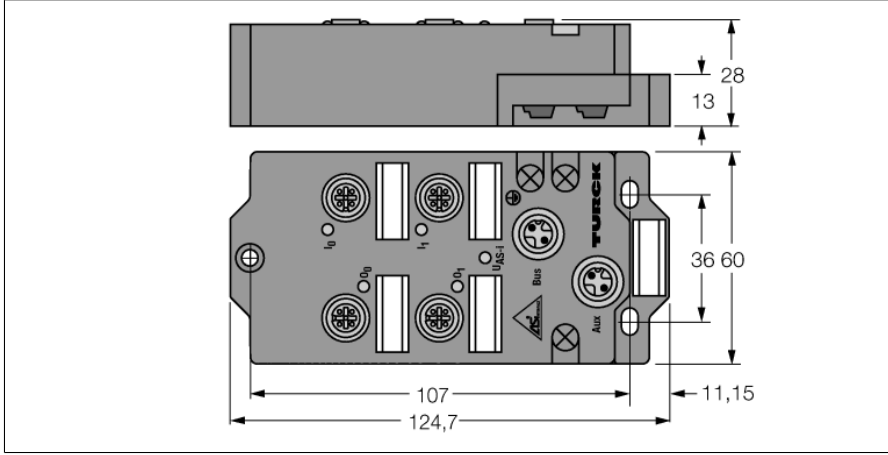

- Bus connected via AS-interface flat cable or male M12 x 1
- Field devices connected via male M12 x 1
- AS-i specification V2.1
- Short-circuit diagnostics
- Cast housing
- Protection class IP67
- Address range 1...31 A/B
- 2 inputs PNP
- 2 outputs PNP
- 24 VDC
- Additional power supply of the outputs


Tip	FAS4-S0202G-A
Tanit. no.	6821327
Kanal sayısı	2/2
Operating / load voltage	18...31 (AS-i) VDC
internal power consumption	<20 mA plus I/O supply
Girişler	
Number of channels	2
Düşük seviye sinyal akımı	<2 mA at 24 VDC
Yüksek seviye sinyal akımı	3...3.4 mA at 24 VDC
Giriş gecikmesi	2.5 ms
Maks. giriş akımı	Total: 200 mA
Çıkışlar	
Number of channels	2
Kanal başına çıkış akımı	700 mA (Aux)
Kısa devre koruması	evet
Fieldbus adres aralığı	1...31 A/B
Fieldbus adresleme	AS-i addressing tool
LEDs Bus	I/O: green = on . red = short-circuit (outputs) AS-i green = OK . red/green = fault
Boyutlar (W x L x H)	60 x 124.7 x 28 mm
Housing material	fibre-glass reinforced Polyamide (PA6-GF30)
Montaj	4 mounting holes Ø 5,4 mm
Ortam sıcaklığı	-25...+70 °C
IP Derecesi	IP67

 Fieldbus




M12 x 1 Giriş

 3-wire pnp sensor



M12 x 1 Çıkış

 DC actuator



Güç Kaynağı

